



Moflash Signalling Ltd

When Safety is Paramount

Meeting the increasing demands of a safety conscious world



Clifford & Snell Products range



Sounder Product Range



CN41



Available in

Red (RAL 3001)
ABS Flame Retardant
10-30vDC


Features




Carillon IP65



Up to 104dB & volume control adjustment

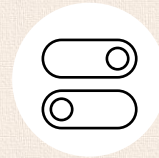

2 stages alarm & 32 selectable tones

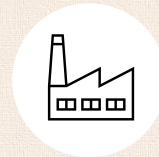

Multi-purpose audible signaling device
designed for indoor applications.



Approved EN54 Pt:3 Fire



Audible signals Electronic Sirens

YA30



Available in

Red (RAL 2002)

ABS Flame Retardant

24/48/110vDC – 115/230vAC

 
Features




MOFLASH
SIGNALLING




Yodalarm 30 IP66



Up to 105dB & volume control adjustment

 

 2 stages alarm & 32 selectable tones.
Independently Selectable 2nd Stage option



Multi-purpose audible signaling device
designed for use in commercial, industrial
& marine application.



Approved EN54 Pt:3 Fire

**Audible signals
Electronic Sirens**



YA40



Available in

Red (RAL 3001) / White (RAL 9003)

ABS Flame Retardant

24/48vDC – 24/115/230vAC

 
Features




MOFLASH
SIGNALLING




Yodalarm 40 IP65



Up to 108dB & volume control adjustment

 

 2 stages alarm & 32 selectable tones.
Independently Selectable 2nd Stage option



Multi-purpose audible signaling device
designed for use in light commercial,
industrial & marine application.



Approved EN54 Pt:3 Fire



Audible signals Electronic Sirens

YA50



Available in

Red (RAL 2002)


ABS Flame Retardant

24/48/110vDC – 24/115/230vAC


Features




Yodalarm 50 IP66

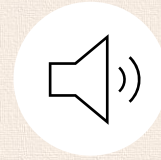

Up to 112dB & volume control adjustment

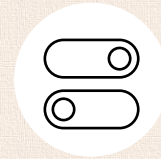

2 stages alarm & 32 selectable tones.
Independently Selectable 2nd Stage option

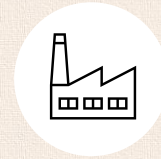

Multi-purpose audible signaling device
designed for use in commercial, industrial
& marine application.



Approved EN54 Pt:3 Fire



Audible signals Electronic Sirens

YA80



Available in

Red (RAL 2002)

ABS Flame Retardant

24/48vDC – 115/230vAC

 
Features




MOFLASH
SIGNALLING




Yodalarm 80 IP66



Up to 116dB

 

 2 stages alarm & 32 selectable tones.
Independently Selectable 2nd Stage



Multi-purpose audible signaling device
high output designed for use in industrial
& marine application.



Approved EN54 Pt:3 Fire



Audible signals Electronic Sirens

YA80S



Available in

Red (RAL 2002)

ABS Flame Retardant

24/48vDC – 115/230vAC

 
Features




MOFLASH
SIGNALLING




Yodalarm 80 Super IP66



Up to 120dB

 

 2 stages alarm & 32 selectable tones.
Independently Selectable 2nd Stage



Multi-purpose audible signaling device
high output designed for use in industrial
& marine application.



Approved EN54 Pt:3 Fire




Audible signals Electronic Sirens


Beacon Product Range



FL40

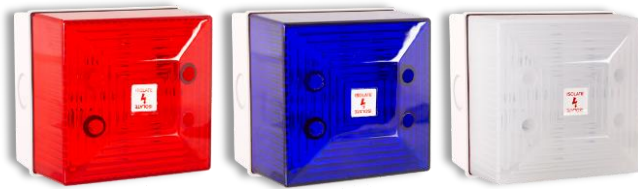

Available in

 

Red (RAL 3001) or White (RAL 9003)

ABS Flame Retardant


Features




Yodac Beacon IP65



Xenon 5J or 2.5J option

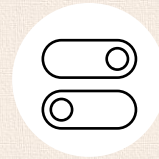

Flashing

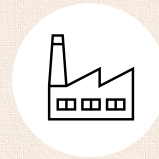

Cost effective solution alarm device for fire alarm systems.




Approved




Visual Signals Beacon

SD40 - FD40

Single

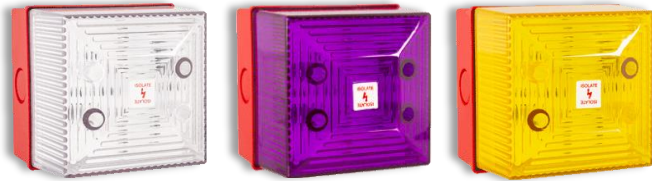

Available in

 

Red (RAL 3001) or White (RAL 9003)

ABS Flame Retardant

 
Features



Yodac Beacon IP65



12 LED array



Static or Flashing



Can be used to alert, warn or draw attention to an event or for a status indication.



Approved




Visual Signals Beacon

SD40 - FD40

Quadruple / Triple / Double



 Available in



Red (RAL 3001) or White (RAL 9003)

ABS Flame Retardant

Features




Choose your own configuration according to your needs.


Lots of different combinations are possible



12 LED array

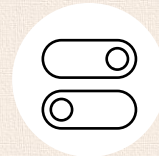

Static or Flashing stackable

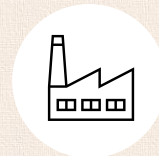

Can be used to alert, warn or draw attention to an event or for a status indication.



Approved



Visual Signals Beacon


Combination Product Range



YL40



 Available in



Red (RAL 3001) or White (RAL 9003)

ABS Flame Retardant

Features




Yodalight 40 IP65



LED or Xenon



Up to 108dB

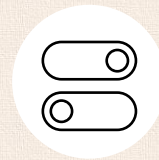

Flashing
2 stages alarm & 32 tones
Independently Selectable 2nd Stage



Approved EN54 Pt:3 Fire




Combination signals Electronic Sirens

YL50



 Available in



Red (RAL 2002)

ABS Flame Retardant


Features




Yodalight 50 IP66



Xenon

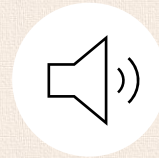

Up to 112dB

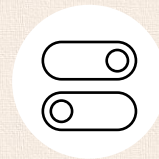

Flashing
2 stages alarm & 32 tones
Independently Selectable 2nd Stage



Approved EN54 Pt:3 Fire

 


Combination signals Electronic Sirens

YL50 Hi Vis



Available in



Red (RAL 2002)

ABS Flame Retardant

Features




Yodalight 50 Hi Vis IP66



12 LED array for 24vDC
25 LED array for 48vDC, 115 & 230vAC



Up to 112dB

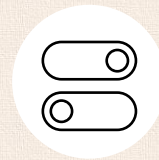

Flashing
2 stages alarm & 32 tones
Independently Selectable 2nd Stage



Approved EN54 Pt:3 Fire




Combination signals Electronic Sirens

YL80



 Available in



Red (RAL 2002)

ABS Flame Retardant


Features




Yodalight 80 IP66



Xenon

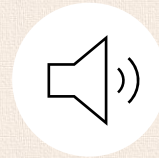

Up to 116dB

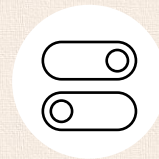

Flashing
2 stages alarm & 32 tones
Independently Selectable 2nd Stage



Approved EN54 Pt:3 Fire

 


**Combination signals
Electronic Sirens**

YL80 Hi Vis



Available in



Red (RAL 2002)

ABS Flame Retardant


Features




Yodalight 80 IP66



12 LED array for 24vDC
25 LED array for 48vDC, 115 & 230vAC

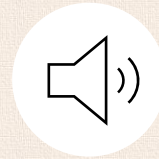

Up to 116dB

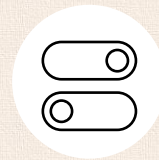

Flashing or Static
2 stages alarm & 32 tones
Independently Selectable 2nd Stage



Approved EN54 Pt:3 Fire




Combination signals Electronic Sirens

YL80S



 Available in



Red (RAL 2002)

ABS Flame Retardant

Features



 
MOFLASH
SIGNALLING




Yodalight 80 Super IP66



Xenon



Up to 120dB

 

Flashing
2 stages alarm & 32 tones
Independently Selectable 2nd Stage



Approved EN54 Pt:3 Fire

 


**Combination signals
Electronic Sirens**

YL80S Hi Vis



Available in



Red (RAL 2002)

ABS Flame Retardant


Features




Yodalight 80 Super IP66



12 LED array for 24vDC
25 LED array for 48vDC, 115 & 230vAC

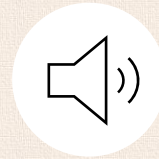

Up to 120dB

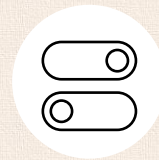

Flashing or Static
2 stages alarm & 32 tones
Independently Selectable 2nd Stage



































Approved EN54 Pt:3 Fire



Combination signals Electronic Sirens

Sounder Tones Table

Description	Hz	Application	Description	Hz	Application
 Alternating	800-1000	Fire Alarm	 Interrupted note	1000	
 Alternating	2500-3100	Security Alarm	 Interrupted note	2500	
 Alternating	800-1000	Increased urgency	 Interrupted note	2500	Pre-vital mess, Sweden
 Alternating	2500-3100	Security deterrent	 Interrupted note	700	
 Alternating	400-554	AFNOR, France	 Interrupted note	1000	Air-raid, Sweden
 Alternating	430-470		 Interrupted note	700	Local warning, Sweden
 Alternating	800-1000		 Interrupted note	700	Industrial alarm, Germany
 Alternating	2500-3200		 Interrupted note	720	
 Alternating	440-554	Turn-out, Sweden	 Int, fast, rising vol	1400	
 Continuous note	700		 Fast siren	250-1200	
 Continuous note	1000		 Rising constant, fall	1000	Industrial alarm, Germany
 Continuous note	1000		 ISO 8201 Evacuation	800-1000	Int'l evacuation alarm
 Continuous note	2300		 Fast whoop	500-1000	
 Continuous note	440		 Slow whoop	500-1200	Evacuation, Netherlands
 Interrupted note	1000		 Reverse sweep	1200-500	Evacuation, Germany
 Interrupted note	420	AS2220, Australia	 Siren	500-1200	

Tones

Get in touch

Contact Us



Head Office

11 Upper Conybere Street
Birmingham, B12 0EB – UK



Sales Enquiry

uksales@moflash.co.uk
+44 (0)121.440.5894



Follow us

www.moflash.co.uk
[@moflashUK / Twitter](#)
[Moflash Signalling Ltd | LinkedIn](#)